




Swivel Ball Hanger

RTU

Pipe Support

Technical Features

- Closure Cylinder Head Screw Sizes : M8x15, M10x18, M12x20
- Finish : Electro Zinc Plated
- Specification : Maximum angle +/- 15°

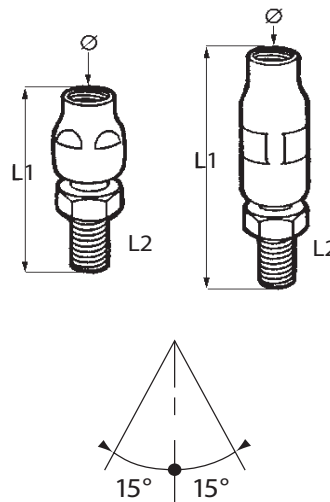

Swivel Ball Hanger - RTU

Physical Data

Reference	Thread	L1 (mm)	L2 (mm)	d (mm)	Box Qty.	Weight (x1) (kg / lbs)
593600	M8x15	66	15	12-15	100	0,04 / 0.09
593610	M10x18	85	18	15-19	100	0,07 / 0.15
593620	M12x20	95	20	20-24	100	0,10 / 0.22