

Test and Drain with Relief and Gauge

1011T


Technical Features

- Sizes available (Nominal) : DN20^{3/4"}, DN25^{1"}, DN32^{1 1/4"}, DN40^{1 1/2"}, DN50^{2"}, .
- Pressure data : Relief valve factory set to operate at 12 bar (175 psi)
- Finish : Red oxide approved for water use.
- Connections : Threaded NPT and BSP.

Test & Drain with R&G -1011T

Materials List

Item	Description	Material
1	Test and Drain Valve	Bronze Body
2	Pressure Relief Valve (Mod. 7000)	Bronze Body
3	Pressure Gauge	
4	1/4" 3-Way Valve (Mod. 7600)	Bronze Body
5	1/2" x 1 1/2" NPT Nipple	
6	1/2" x 1/2" x 1/4" Tee	
7	1/4" Nipple	
8	1/4" Plug	
9	2 1/2" NPT x Barb 90° Elbows	
10	1 - Nylobraid Drain Tubing	
11	2 x Clamps	

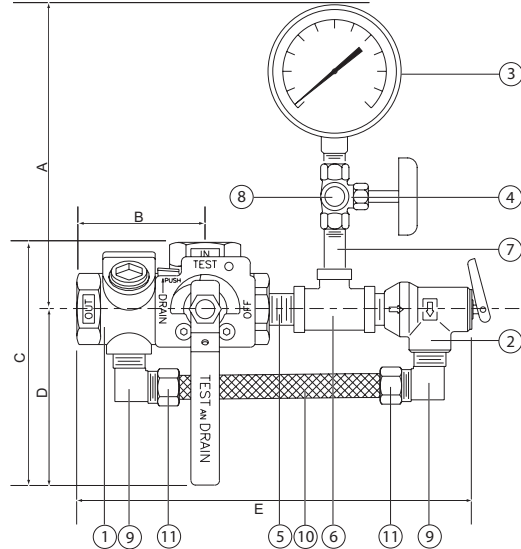

Test & Drain Valves

Test and Drain with Relief and Gauge -1011T

Physical Data

Nominal Size		Dimensions (mm / inch)					Orifice Nominal K-Factor		Reference		Weight (kg / lbs)
Metric	inch	A	B	C	D	E	Metric	US	NPT Thread	BSP Thread	
DN20	3/4"	256 / 10.3	84 / 3.4	119 / 8.8	114 / 4.5	334 / 13.4	40	2.8	1011T-0750375	1011T-0750375B	2.8 / 6.1
							57	4.2	1011T-0750440	1011T-0750440B	
							80	5.5	1011T-0750500	1011T-0750500B	
							115	8.0	1011T-0750530	1011T-0750530B	
DN25	1"	256 / 10.3	84 / 3.4	119 / 8.8	114 / 4.5	334 / 13.4	40	2.8	1011T-0100375	1011T-0100375B	2.2 / 4.8
							57	4.2	1011T-0100440	1011T-0100440B	
							81	5.5	1011T-0100500	1011T-0100500B	
							115	8.0	1011T-0100530	1011T-0100530B	
DN32	1 1/4"	263 / 10.5	91 / 3.6	225 / 9.0	139 / 5.6	363 / 14.5	40	2.8	1011T-0125375	1011T-0125375B	2.8 / 6.1
							57	4.2	1011T-0125440	1011T-0125440B	
							80	5.5	1011T-0125500	1011T-0125500B	
							115	8.0	1011T-0125530	1011T-0125530B	
							161	11.2	1011T-0125ELO	1011T-0125ELOB	
DN40	1 1/2"	288 / 11.5	97 / 3.9	242 / 9.7	206 / 8.3	447 / 17.9	40	2.8	1011T-0150375	1011T-0150375B	5.3 / 11.7
							57	4.2	1011T-0150440	1011T-0150440B	
							80	5.5	1011T-0150500	1011T-0150500B	
							115	8.0	1011T-0150530	1011T-0150530B	
							161	11.2	1011T-0150ELO	1011T-0150ELOB	
DN50	2"	288 / 11.5	97 / 3.9	242 / 9.7	206 / 8.3	447 / 17.9	40	2.8	1011T-0200375	1011T-0200375B	5.3 / 11.7
							57	4.2	1011T-0200440	1011T-0200440B	
							80	5.5	1011T-0200500	1011T-0200500B	
							115	8.0	1011T-0200530	1011T-0200530B	
							161	11.2	1011T-0200ELO	1011T-0200ELOB	
							202	14.0	1011T-0200ESFR	1011T-0200ESFRB	