



Section E
Special Sprinklers

TABLE OF CONTENTS

Institutional - VK410/VK412, 5.6 (81) K factor, flush pendent / flush horizontal sidewall.....E-1
 Combustible Interstitial Space - VK900, VK950, COIN[®], uprightE-1
 Model V-BB specific application attic sprinkler - VK684, VK685, VK686, VK681, VK682, VK683E-2
 Model V-SD specific application attic sprinkler - VK693, VK694, VK695E-2
 Attic upright specific application sprinkler – VK696E-2


Notes


1. Unless otherwise indicated, all cover plates and escutcheons are sold separately.
2. Cover plates, escutcheons, and sprinklers are available in custom colors at an additional charge. See pages F-8 and F-9 for details.
3. Refer to Viking technical data pages for complete product specifications. You may print or download technical data by visiting www.vikinggroupinc.com.
4. List prices effective June 4, 2016. Supersedes May 2015 list price book.
5. All sales by Viking are subject to the Terms & Conditions found on the last page of this book.

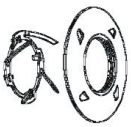
COIN[®] is a registered trademark of The Viking Corporation
Micromatic[®] is a registered trademark of The Viking Corporation


	COIN[®] Quick Response COmbustible INterstitial Glass Bulb Upright			
	SIN:	VK900		
	K Factor:	4.2 (60)		
	Thread Size:	1/2 inch NPT		
	Base Part #:	12493		
Finish	Temp	Part #	IPG	List Price
Standard Brass	175°F	12493AD	V14.3	\$60.46
FUSIBLE LINK - VK901 (4.2 (60) K Factor)				
Standard Brass	205°F	12676AE	V14.3	\$66.67
Std Sprinkler Wrench		10896W/B	V20	\$67.72

	COIN[®] Quick Response COmbustible INterstitial Glass Bulb Upright (Specific Application)			
	SIN:	VK950		
	K Factor:	5.6 (80)		
	Thread Size:	1/2 inch NPT		
	Base Part #:	20757		
Finish	Temp	Part #	IPG	List Price
Standard Brass	200°F	20757AE	V14.3	\$74.06
Std Sprinkler Wrench		10896W/B	V20	\$67.72

	Institutional^{2,3} Quick Response Extended Coverage Fusible Link Flush Pendent			
	SIN:	VK410		
	K Factor:	5.6 (81)		
	Thread Size:	1/2 inch NPT		
	Base Part #:	10554		
Finish	Temp	Part #	IPG	List Price
Polished Chrome	165°F	10554FC	V17.1	\$62.50
Polished Chrome	220°F	10554FF	V17.1	\$62.50
Heavy Duty Spk Wrench		08336W/B	V20	\$130.44
Light Duty Spk Wrench		10366W/B	V20	\$30.88


	Institutional^{2,3} Quick Response Standard Coverage Fusible Link Flush Horizontal Sidewall			
	SIN:	VK412		
	K Factor:	5.6 (81)		
	Thread Size:	1/2 inch NPT		
	Base Part #:	10579		
Finish	Temp	Part #	IPG	List Price
Polished Chrome	165°F	10579FC	V17.1	\$73.57
Polished Chrome	220°F ¹	10579FF	V17.1	\$73.57
Heavy Duty Spk Wrench		08336W/B	V20	\$130.44
Light Duty Spk Wrench		10366W/B	V20	\$30.88


	Institutional Escutcheon / Lock Ring Pkg³ <i>(3-1/4 inch diameter)</i>			
	Finish	Part #	IPG	List Price
Polished Chrome	10627F	V17.1	\$25.94	
Esc Installation Wrench	10551W/B	V20	\$44.57	
Spanner Wrench-Removal	10729	V20	\$148.61	


	Institutional Optional Retaining Flange and Screw Assembly³			
	Finish	Part #	IPG	List Price
Polished Chrome	10599	V17.1	\$37.89	

- (1) 220°F institutional flush sidewall is not listed or approved.
- (2) For institutional sprinklers, once lock ring is installed and escutcheon is threaded, the escutcheon cannot be removed without damage to the sprinkler or escutcheon.
- (3) Institutional sprinklers and escutcheon/lock ring packages are sold separately.
- (4) Electroless Nickel PTFE (ENT) plating is UL Listed for corrosion resistance.

Specific Application Attic Sprinklers

	Back-to-Back (Model V-BB) Attic Sprinkler, Specific Application, Glass Bulb, ½ and ¾ inch NPT							
	K Factor	Roof Pitch	SIN	Part #	Temp	Finish ¹	IPG	List Price
	5.6 (81)	4:12 < 7:12	VK684	19627AE	200°F	Standard Brass	V14.5	\$ 329.60
	5.6 (81)	7:12 < 10:12	VK685	19801AE	200°F	Standard Brass	V14.5	\$ 329.60
	5.6 (81)	10:12 ≤ 12:12	VK686	19754AE	200°F	Standard Brass	V14.5	\$ 329.60
	8.0 (115)	4:12 < 7:12	VK681	19626AE	200°F	Standard Brass	V14.5	\$ 384.53
	8.0 (115)	7:12 < 10:12	VK682	19798AE	200°F	Standard Brass	V14.5	\$ 384.53
8.0 (115)	10:12 ≤ 12:12	VK683	19751AE	200°F	Standard Brass	V14.5	\$ 384.53	

	Single Directional (Model V-SD) Attic Sprinkler, Specific Application, Glass Bulb, ½ inch NPT							
	K Factor	Roof Pitch	SIN	Part #	Temp	Finish ¹	IPG	List Price
	5.6 (81)	4:12 < 7:12	VK693	19578AE	200°F	Standard Brass	V14.5	\$ 329.60
	5.6 (81)	7:12 < 10:12	VK694	19799AE	200°F	Standard Brass	V14.5	\$ 329.60
5.6 (81)	10:12 ≤ 12:12	VK695	19759AE	200°F	Standard Brass	V14.5	\$ 329.60	

	Attic Upright Sprinkler, Specific Application, Glass Bulb, ½ inch NPT							
	K Factor	Roof Pitch	SIN	Part #	Temp	Finish ¹	IPG	List Price
4.2 (57)	4:12 to 12:12	VK696	19538AE	200°F	Standard Brass	V14.4	\$ 48.22	

Installation Wrench	Part #	IPG	List Price
Standard Wrench	10896W/B	V20	\$ 67.72

(1) Also available with Electroless Nickel PTFE (ENT) plating for corrosion resistance (special order with extended lead time).
Contact customer service for price and availability.

