

Standard Response

8.0 (115) K Factor (17/32" orifice)
Standard Coverage
Horizontal Sidewall / 1" NPT
Glass Bulb


To order, add finish, temperature and length suffix to base part number (length = A dimension, inches)

Ex: **VK2543, chrome, 175 °F, 17 1/4" long**
Part Number: 21481UFD1725

VK2503 Plain Barrel Base P/N: <u>21493U</u>	VK2523 Standard Adjustable Base P/N: <u>21487U</u>	VK2543 Recessed Adjustable Base P/N: <u>21481U</u>
NEW! Now cULus Listed with 12" deflector distance down from ceiling		
order in 1/2" increments	order in 1/2" increments	order in 1/4" increments

Item Price Group: V187 (ENT Finish: IPG V188)


VK2503 - Plain Barrel	Length (L) - A Dimension	LIST PRICES and Available Finishes		
base p/n - 21493U(f)(t)(l)		Standard Brass (A_)	Polished Chrome (F_)	ENT (JN) IPG V188
	3 - 6" (76 - 152mm)	\$268.20	\$270.71	P.O.A.
	6 1/2 - 9" (165 - 229mm)	\$282.63	\$285.15	P.O.A.
	9 1/2 - 12" (241 - 305mm)	\$289.88	\$292.43	\$370.64
	12 1/2 - 15" (318 - 381mm)	\$318.90	\$321.39	P.O.A.
	15 1/2 - 18" (394 - 457mm)	\$340.66	\$340.66	P.O.A.
	18 1/2 - 21" (470 - 533mm)	\$355.13	\$357.65	P.O.A.
	21 1/2 - 24" (546 - 610mm)	\$391.35	\$393.84	P.O.A.
	24 1/2 - 27" (622 - 686mm)	\$413.11	\$415.65	P.O.A.
	27 1/2 - 30" (699 - 762mm)	P.O.A.	\$433.77	P.O.A.
	30 1/2 - 33" (775 - 838mm)	P.O.A.	P.O.A.	P.O.A.
	33 1/2 - 36" (851 - 914mm)	\$467.46	P.O.A.	P.O.A.

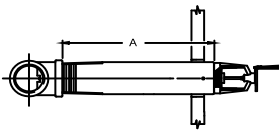

*contact customer service for lengths over standard

Item Price Group: V187 (ENT Finish: IPG V188)


VK2523 - Standard Adj.	Length (L) - A Dimension	LIST PRICES and Available Finishes		
base p/n - 21487U(f)(t)(l)		Polished Chrome (F_)	White (M_/W)	ENT (JN) IPG V188
	1 1/2 - 6" (38 - 152mm)	\$282.63	\$282.63	P.O.A.
	6 1/2 - 9" (165 - 229mm)	\$289.88	\$289.88	P.O.A.
	9 1/2 - 12" (241 - 305mm)	\$297.18	\$297.18	\$375.42
	12 1/2 - 15" (318 - 381mm)	\$322.52	\$322.53	P.O.A.
	15 1/2 - 18" (394 - 457mm)	\$333.41	\$333.41	P.O.A.
	18 1/2 - 21" (470 - 533mm)	\$358.73	\$358.73	\$436.98
	21 1/2 - 24" (546 - 610mm)	\$380.45	\$380.46	\$458.68
	24 1/2 - 27" (622 - 686mm)	\$405.87	\$405.87	P.O.A.
	27 1/2 - 30" (699 - 762mm)	\$423.96	\$423.97	\$502.21
	30 1/2 - 33" (775 - 838mm)	\$434.79	\$434.79	P.O.A.
	33 1/2 - 36" (851 - 914mm)	\$460.20	P.O.A.	P.O.A.

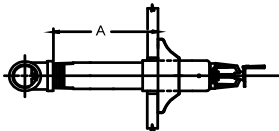

*contact customer service for lengths over standard

Item Price Group: V187 (ENT Finish: IPG V188)

VK2543 - Recessed Adj.	Length (L) - A Dimension	LIST PRICES and Available Finishes		
base p/n - 21481U(f)(t)(l)		Polished Chrome (F_)	White (M_/W)	ENT (JN) IPG V188
	3 1/4 - 6" (83 - 152mm)	\$282.63	\$289.87	P.O.A.
	6 1/4 - 9" (159 - 229mm)	\$289.87	\$297.16	P.O.A.
	9 1/4 - 12" (235 - 305mm)	\$297.18	\$304.38	\$382.64
	12 1/4 - 15" (311 - 381mm)	\$322.53	\$329.74	P.O.A.
	15 1/4 - 18" (387 - 457mm)	\$340.66	\$347.85	P.O.A.
	18 1/4 - 21" (464 - 533mm)	\$362.33	\$369.59	P.O.A.
	21 1/4 - 24" (540 - 610mm)	\$384.13	\$391.34	P.O.A.
	24 1/4 - 27" (616 - 686mm)	\$413.11	P.O.A.	P.O.A.
	27 1/4 - 30" (692 - 762mm)	\$427.60	\$434.82	P.O.A.
	30 1/4 - 33" (768 - 838mm)	\$442.08	\$449.32	P.O.A.
	33 1/4 - 36" (845 - 914mm)	P.O.A.	\$420.36	P.O.A.

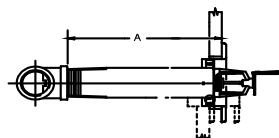

Additional Ordering Information
VK2503/2523/2543

Available Temp. Ratings / Suffix

155°F (68°C) = B
175°F (79°C) = D
200°F (93°C) = E
286°F (93°C) = G *
* N/A with VK254

VK2523 also available in white finish with chrome escutcheon at same price as white finish. Use suffix MF_/W

Standard Wrench

VK2503 and VK2523
07297W/B \$106.76

Recessed Wrench for VK2543 Model

07565W/B \$137.03

Dry Spk Replacement Escutcheons

Std. Adj. - Chrome
08086F \$7.10

Std. Adj. - White
08086M/W \$7.10

Rec. Adj. - Chrome
05459AF \$5.16

Rec. Adj. - White
05459AM/W \$5.16

Dry Sprinkler Boot

22087M/W \$46.86

Electroless Nickel PTFE (ENT) coating is for corrosion resistance.