

# Fire Department Connections

## Fire Department Connections – Single Clapper Siamese, UL Listed FM Approved

FPPI Fire Department Connections are UL Listed and FM Approved in accordance with NFPA. Standard configuration is 4" NPT x 2-1/2" x 2-1/2" NST Swivels. A limited number of regional threads are available for the swivels. Each FDC features solid brass construction and single clapper design.



Part No.	Description	Box Qty.
09-000	FDC Straight NST 4" x 2.5" x 2.5"	6
09-002	FDC Straight BCT 4" x 2.5" x 2.5"	6
09-004	FDC Straight QST 4" x 2.5" x 2.5"	6
09-006	FDC Straight ONT 4" x 2.5" x 2.5"	6
09-008	FDC Straight PHX 4" x 2.5" x 2.5"	6
09-010	FDC Straight TEM 4" x 2.5" x 2.5"	6
09-012	FDC Straight CLV 4" x 2.5" x 2.5"	6
09-014	FDC Straight DET 4" x 2.5" x 2.5"	6
09-020	FDC 90 NST 4" x 2.5" x 2.5"	6

## Fire Department Connections – Single Outlet for Residential Sprinkler System, UL Listed

FPPI Single Outlet FDC is the only UL Listed FDC of this type and is ideal for residential applications where required. Features integral identification plate (AUTO SPRINKLER) and comes complete with 1-1/2" NST plug and chain. Predrilled for mounting to finished building surface. Solid brass.



Part No.	Description	Box Qty.
09-502	FDC 1-1/2" NPT x NST w/plug UL	24

## GrooveFit® FDC – Single Clapper Siamese, UL Listed, FM Approved

FPPI GrooveFit® Fire Department Connections are UL Listed and FM Approved in accordance with NFPA. Standard configuration is 4" Groove Outlet x 2-1/2" x 2-1/2" NST PL Swivels Inlets. Each FDC features solid brass construction and single clapper design. Available in straight or 90 degree pattern. Rigid style couplings are recommended for a secure installation. Patent Pending.



Part No.	Description	Box Qty.
09-070	GrooveFit® FDC St 4G x 2.5x2.5NST	6
09-090	GrooveFit® FDC 90 4G x 2.5x2.5NST	4




# Fire Department Connections



## Open Snoot Assembly

Each kit contains one open snoot, 2-1/2" IPS brass wall plate (AUTO SPRINKLER) and a 2-1/2" plug with chain, boxed and labeled. A limited number of regional threads are available.

Part No.	Description	Box Qty.
09-650	Open Snoot 2.5" NST Assembly	10
09-652	Open Snoot 2.5" BCT Assembly	10
09-654	Open Snoot 2.5" QST Assembly	10
09-656	Open Snoot 2.5" ONT Assembly	10
09-658	Open Snoot 2.5" PHX Assembly	10
09-660	Open Snoot 2.5" TEM Assembly	10
09-662	Open Snoot 2.5" CLV Assembly	10
09-664	Open Snoot 2.5" DET Assembly	10

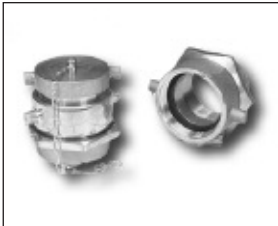

## Open Snoots

FPPI Open Snoots feature all brass construction. Standard configuration is 2-1/2" NPT Outlet x 2-1/2" NST Swivel Inlet. A limited number of regional threads are available.

Part No.	Description	Box Qty.
09-600	Open Snoot 2.5 FNPT x FNST PL RB	24
09-602	Open Snoot 2.5 FNPT x FBCT PL RB	24
09-604	Open Snoot 2.5 FNPT x FQST PL RB	24
09-606	Open Snoot 2.5 FNPT x FONT PL RB	24
09-608	Open Snoot 2.5 FNPT x FPHX PL RB	24
09-610	Open Snoot 2.5 FNPT x FTEM PL RB	24
09-612	Open Snoot 2.5 FNPT x FCLV PL RB	24
09-614	Open Snoot 2.5 FNPT x FDET PL RB	24

*See page 29 for additional thread information.*