


## Features

- Eliminates wood "blocking" materials and labor
- No spacer or backup blocks required
- Fastest offset CPVC support
- Positions CPVC pipe 1-1/2" off the surface
- Available for 3/4" - 2" CPVC pipe

# Stand-Off 2-Hole Strap Hanger

For CPVC Fire Protection Piping

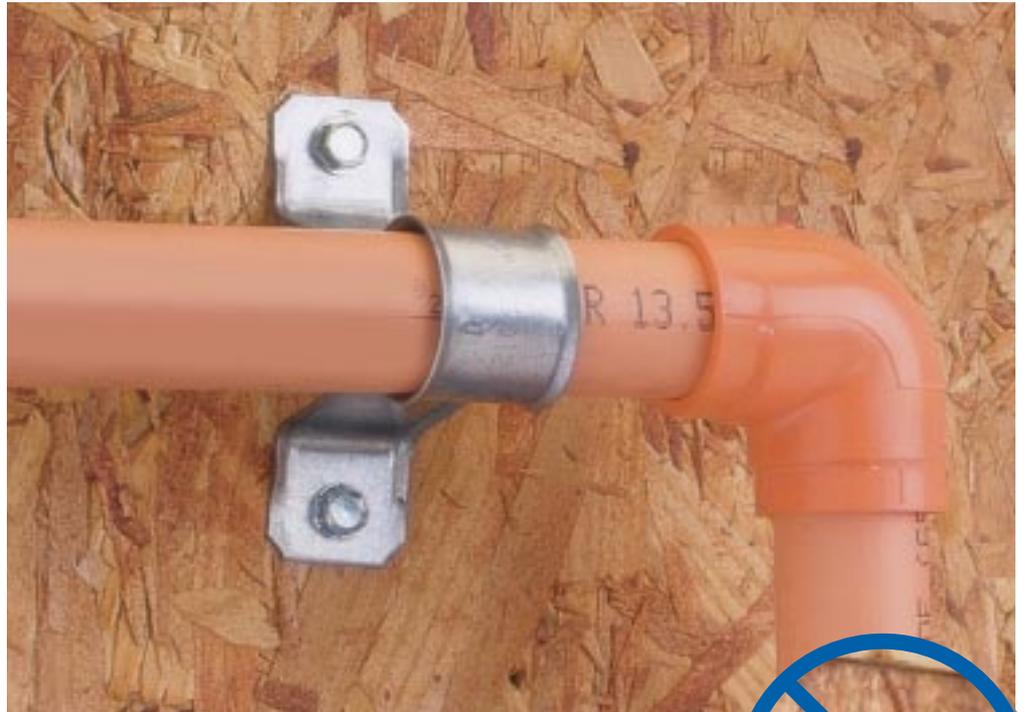

## Installation



1. Snap strap over CPVC pipe.



2. Squeeze strap back around pipe. (NOTE: Pipe must be allowed to move freely)



3. Fasten the strap to the wood surface using the two screws provided. (#10 x 1 hex washer head unslotted, self-tapping.)

The SO series hanger for CPVC pipe was tested on a 3/8" thick OSB web, composite wood joist without the use of a traditional wood block and passed the UL 203 test criteria.

**No Backup Blocks Are Required!**

COMPLIES WITH STATIC LOAD REQUIREMENTS OF NFPA13



# Stand-Off 2-Hole Strap Hanger

For CPVC Fire Protection Piping

## SO SERIES STAND-OFF HANGERS

### FEATURES

- For mounting CPVC pipe to structural wood or composite wood joists with a minimum 3/8" web thickness.
- Eliminates wood "blocking" materials and labor (No spacer or backup blocks required).
- Fastest offset support for CPVC.
- Positions CPVC pipe 1-1/2" off the surface.
- Available for 3/4" - 2" CPVC pipe.
- #10 hex head cap screws included.
- Complies with static load requirements of NFPA13.

### We Also Have:



107 Series



108 Series




109 Series




### Applications

CADDY® SO Series  
Stand-Off Hanger


Old Method

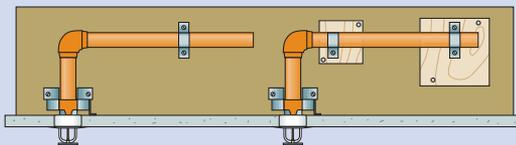

Solid Wood Joist

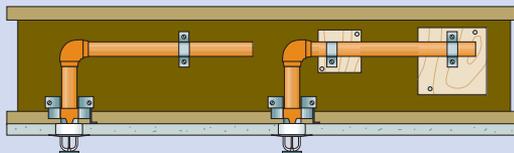

Composite Wood Joist

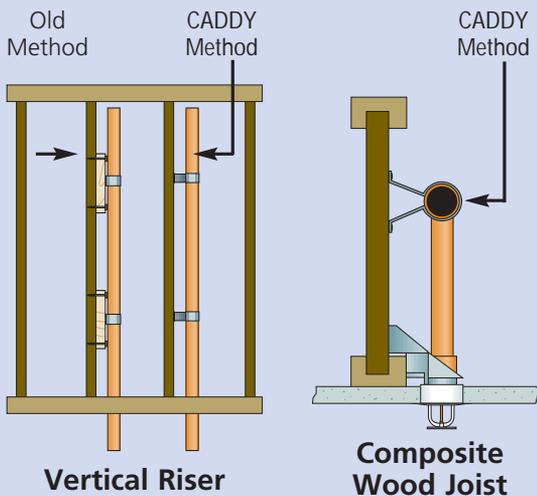

Distributed By:

UPC Code	Catalog Number	Description	
39810	SO12A	Stand-Off 2 Hole Strap for 3/4" CPVC pipe	100
39811	SO16A	Stand-Off 2 Hole Strap for 1" CPVC pipe	100
39812	SO20A	Stand-Off 2 Hole Strap for 1-1/4" CPVC pipe	100
39813	SO24A	Stand-Off 2 Hole Strap for 1-1/2" CPVC pipe	100
39814	SO32A	Stand-Off 2 Hole Strap for 2" CPVC pipe	100
36122	1070075EG	#107 Wrap Around Strap CPVC 3/4	100
36123	1070100EG	#107 Wrap Around Strap CPVC 1	100
36124	1070125EG	#107 Wrap Around Strap CPVC 1-1/4	100
36125	1070150EG	#107 Wrap Around Strap CPVC 1-1/2	100
36126	1070200EG	#107 Wrap Around Strap CPVC 2	100
36127	1080075EG	#108 Two Hole Strap CPVC 3/4	100
36128	1080100EG	#108 Two Hole Strap CPVC 1	100
36129	1080125EG	#108 Two Hole Strap CPVC 1-1/4	100
36130	1080150EG	#108 Two Hole Strap CPVC 1-1/2	100
36131	1080200EG	#108 Two Hole Strap CPVC 2	100
36132	1090075EG	#109 Side Mount Strap CPVC 3/4	100
36133	1090100EG	#109 Side Mount Strap CPVC 1	100
36134	1090125EG	#109 Side Mount Strap CPVC 1-1/4	100
36135	1090150EG	#109 Side Mount Strap CPVC 1-1/2	100
36136	1090200EG	#109 Side Mount Strap CPVC 2	100
#10 x 1 hex head cap screws included			

### INSTALLATION TOOL OPTIONS



Nut Driver



Wrench



WARNING – ERICO products shall be used only as illustrated and recommended in the product instruction sheets (additional instruction sheets are available at [www.erico.com](http://www.erico.com)). Misuse or misapplication may cause failure resulting in possible property damage or bodily injury.

Copyright ©2004 ERICO International Corporation. All rights reserved.

CADDY, CADWELD, CRITEC, ERICO, ERIFLEX, ERITECH, and LENTON are registered trademarks of ERICO International Corporation.

Phone: 800-333-0852

Fax: 800-677-5403

[www.erico.com](http://www.erico.com)