

## Description

LubeFit® is a vegetable fiber based lubricant for all gasketed fittings, including grooved couplings for fire sprinkler systems. It is non staining\* and does not support bacterial growth. LubeFit® can be easily applied in temperatures from -10°F to 150°F. LubeFit® is non-toxic and water soluble. Under normal conditions, LubeFit® is not harmful to the skin.




## Design Criteria/Data

- Water dispersible
- Applies equally well to wet or dry surfaces
- Suitable for all types of pipe lines, including potable water
- Excellent working range -10° to 150°
- Will not support bacteria
- Will not deteriorate natural or Synthetic rubber, plastic gaskets or caston iron pipe
- FGG/BM/CZ™ System Compatible Program\*
- Certified to NSF/ANS/Std 61-G



\*FBC™ System Compatible indicates this product has been tested by Lubrizol Advanced Materials and is monitored on an on going basis to assure chemical compatibility with FlowGuard Gold®, BlazeMaster®, and Corzan® pipe and fittings.

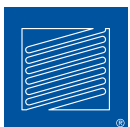

3198 LIONSHEAD AVE  
CARLSBAD, CA 92010  
TEL + 1 760 599-1168  
+ 1 800 344-1822  
FAX + 1 800 344-3775

## Application

LubeFit® should be applied in an even and thin amount over the parts to be lubricated. Avoid applying excessive amounts. The best applicaion is achieved when applying by hand. Clean all dirt, burrs and foreign matter from the joint surfaces. Make certain the gasket is properly located. Apply an even coating of lubricant to all fitting surfaces and gasket. Assemble the joint according to the pipe fitting manufacturer's directions.

## Disclaimer

DO NOT ALTER THE CONSISTENCY OF THIS PRODUCT. Use as is directly from the container. Keep away from your mouth and eyes. If eye contact occurs, fl ush with water for 5 minutes. If discomfort persists get medical attention. \*Will stain untreated porous surfaces such as concrete if not cleaned from the surface immediately.

## Specifications

### Appearance:

Dense, paste like consistency and is light brown or tan in color.

### Contains:

Potassium Oleate, Propylene Glycol and Mica. Contains NO PETROLEUM.

### Packaging:

2lb (1-quart approx.)  
55-gal drum  
(400 lbs. approx.)

See Material Safety Data Sheet for additional safety and disposal information at [www.fpfi.com](http://www.fpfi.com)

*CAUTION: Eye irritant.  
Avoid contact with eyes.  
Wash thoroughly after use.*