

VIKING DRY SPRINKLER ORDER FORM

Customer: _____

Ship to: _____

Date: _____


PO#/Job: _____

Dry sprinklers are custom made and NOT RETURNABLE. Please follow these steps to ensure an accurate order

1. Check the desired SIN (Sprinkler Identification Number).
2. Check desired sprinkler finish and temperature.
(Circle temp and finish for fusible link models.)
3. Enter A or B dimensions - see page 2 for dimensional references.
4. Enter order quantity.

A Dimension is the distance from the face of the fitting (tee) to desired finished surface of ceiling.

B Dimension is the distance from the face of the fitting (tee) to the top of the deflector - upright models only.

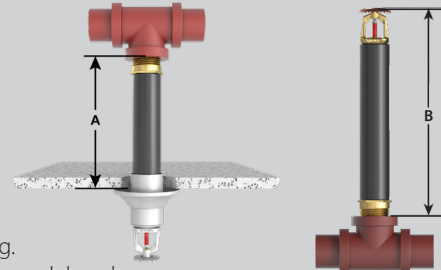

Standard Adjustable	Pendent	ELO Pendent	Horizontal Sidewall	Vertical Sidewall	Finish	Recessed Flush	Pendent	Finish
	<input type="checkbox"/> VK154 (SR) <input type="checkbox"/> VK163 (SR LO) <input type="checkbox"/> VK176 (QR) <input type="checkbox"/> VK177 (QR LO) <input type="checkbox"/> VK286 (QR LO*) *Fusible Link 165° 205° 280° (Circle temp) 	<input type="checkbox"/> VK546 (SR ELO)* <input type="checkbox"/> VK549 (QR ELO)* *Fusible Link 165° 205° 280° Brass Chrome White (Circle temp and finish) Lengths in 6" increments, 12"-28" Note: Insulating boot included.	<input type="checkbox"/> VK156 (SR) <input type="checkbox"/> VK2523 (SR OH) <input type="checkbox"/> VK178 (QR) <input type="checkbox"/> VK2773 (QR OH) <input type="checkbox"/> VK2883 (QR OH*) *Fusible Link 165° 205° 280° (Circle temp) 	<input type="checkbox"/> VK 157 (SR)* *Available in Chrome only 	<input type="checkbox"/> Chrome (F) <input type="checkbox"/> White (M) <input type="checkbox"/> White w/chrome escutcheon & sleeve (MF) <input type="checkbox"/> ENT (JN) Temperature <input type="checkbox"/> 155°F (68°C) (B) <input type="checkbox"/> 175°F (79°C) (D) <input type="checkbox"/> 200 °F (93°C) (E) <input type="checkbox"/> 286°F (141°C) (G)		<input type="checkbox"/> VK482 (QR) 	<input type="checkbox"/> White Polyester (M-/W) Temperature <input type="checkbox"/> 165°F (74°C) (C) <input type="checkbox"/> 205 °F (96°C) (E)
Lengths in 1/2" increments					Lengths in 1/4" increments			

Recessed Adjustable	Pendent	ELO Pendent	Horizontal Sidewall	Vertical Sidewall	Finish	Concealed	Pendent	Finish
	<input type="checkbox"/> VK158 (SR) <input type="checkbox"/> VK164 (SR LO) <input type="checkbox"/> VK186 (SR**) <input type="checkbox"/> VK169 (SR***) <input type="checkbox"/> VK180 (QR) <input type="checkbox"/> VK181 (QR LO) <input type="checkbox"/> VK186 (QR**) <input type="checkbox"/> VK290 (QR LO*) *Fusible Link 165° 205° **Ext. Coverage 155° 175° (Circle temp) ***Stainless Steel 	<input type="checkbox"/> VK545 (SR ELO)* <input type="checkbox"/> VK548 (QR ELO)* *Fusible Link 165° 205° 280° Brass Chrome White (Circle temp and finish) Lengths in 6" increments, 12"-28" Note: Insulating boot included.	<input type="checkbox"/> VK162 (SR) <input type="checkbox"/> VK2543 (SR OH) <input type="checkbox"/> VK188 (SR**) <input type="checkbox"/> VK182 (QR) <input type="checkbox"/> VK2793 (QR OH) <input type="checkbox"/> VK188 (QR**) <input type="checkbox"/> VK2923 (QR OH*) *Fusible Link 165° 205° **Ext. Coverage 155° 175° (Circle temp) 	<input type="checkbox"/> VK449 (RES)* *Residential 155° 200° (Circle temp) 	<input type="checkbox"/> Chrome (F) <input type="checkbox"/> White (M) <input type="checkbox"/> ENT (JN) Temperature <input type="checkbox"/> 155°F (68°C) (B) <input type="checkbox"/> 175°F (79°C) (D) <input type="checkbox"/> 200 °F (93°C) (E) Lengths in 1/4" increments		<input type="checkbox"/> VK190 (SR) <input type="checkbox"/> VK192 (SR LO) <input type="checkbox"/> VK196 (SR**) <input type="checkbox"/> VK194 (QR) <input type="checkbox"/> VK196 (QR***) **SR Ext Cov 155° ***QR Ext Cov 135° 155° 175° (Circle temp) 	<input type="checkbox"/> Chrome (F) <input type="checkbox"/> White (M) <input type="checkbox"/> Ivory (M-/I) <input type="checkbox"/> Black (M-/B) Temperature Sprinklers <input type="checkbox"/> 155°F (68°C) (B) <input type="checkbox"/> 175°F (79°C) (D) <input type="checkbox"/> 200 °F (93°C) (E) Covers <input type="checkbox"/> 135°F (57°C) (A) <input type="checkbox"/> 165°F (74°C) (C)
Lengths in 1/4" increments					Lengths in 1/4" increments			

Plain Barrel	Pendent	ELO Pendent	Horizontal Sidewall	Vertical Sidewall	Upright	Finish	A or B Dim:	Qty:
	<input type="checkbox"/> VK150 (SR) <input type="checkbox"/> VK166 (SR LO) <input type="checkbox"/> VK168 (SR**) <input type="checkbox"/> VK172 (QR) <input type="checkbox"/> VK173 (QR LO) <input type="checkbox"/> VK282 (QR LO*) *Fusible Link 165° 205° 280° (Circle temp) **Stainless Steel 	<input type="checkbox"/> VK544 (SR ELO)* <input type="checkbox"/> VK547 (QR ELO)* *Fusible Link 165° 205° 280° Brass Chrome White (Circle temp and finish) Lengths in 6" increments, 12"-48" Note: Insulating boot included.	<input type="checkbox"/> VK152 (SR) <input type="checkbox"/> VK2503 (SR OH) <input type="checkbox"/> VK174 (QR) <input type="checkbox"/> VK2753 (QR OH) <input type="checkbox"/> VK2843 (QR OH*) *Fusible Link (165°, 205°, 280°) (Circle temp) 	<input type="checkbox"/> VK153 (SR) 	<input type="checkbox"/> VK160 (SR)* <input type="checkbox"/> VK184 (QR)* *Available in Brass only 	<input type="checkbox"/> Chrome (F) <input type="checkbox"/> Brass (A) <input type="checkbox"/> ENT (JN) Temperatures <input type="checkbox"/> 155°F (68°C) (B) <input type="checkbox"/> 175°F (79°C) (D) <input type="checkbox"/> 200 °F (93°C) (E) <input type="checkbox"/> 286°F (141°C) (G) Lengths in 1/2" increments		

